


Technical data sheet

Connection clamp AB EX ISG, straight

Item number: 5240360



Connection clamp for mounting the OBO Ex spark gap, type EX ISG, on insulating flanges and insulating pieces.

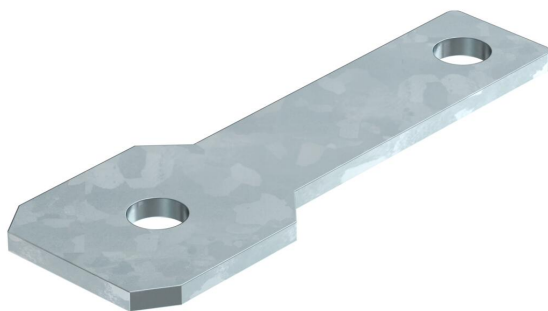

St

Steel

FT

Hot-dip galvanised

Master data

Item number	5240360
Type	AB EX ISG S M10
Description 1	Connection bracket
Description 2	straight version
Manufacturer	OBO
Dimension	120x45x40
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Piece
Weight	9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4465 kg CO2e / 1 Piece


Technical data sheet

Connection clamp AB EX ISG, straight

Item number: 5240360



Dimensions

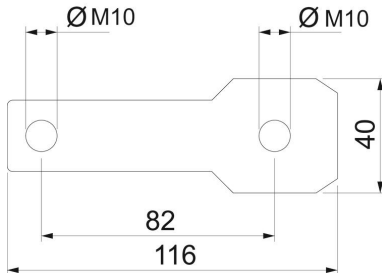

Technical data

Type of accessory	Connection element
Version for	For M10 bolt
Drill hole diameter, min.	11 mm
ROHS-conformant	yes
Accessories	yes
Spare part	no