

Technical data sheet

Connector, Rd 8–10 mm with M10 thread

Item number: 5304008



- With bore hole 10.2 mm
- With thread M10
- Including pre-mounted nut M10 and serrated washer
- Conforms to the requirements according to DIN VDE 0185-305 (IEC 62305)

St	Steel
F	Hot galvanised

Master data

Item number	5304008
Type	5000
Description 1	Connection terminal
Description 2	for round conductors
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	4.63 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1488 kg CO2e / 1 Piece


Technical data sheet

Connector, Rd 8–10 mm with M10 thread

Item number: 5304008



Dimensions

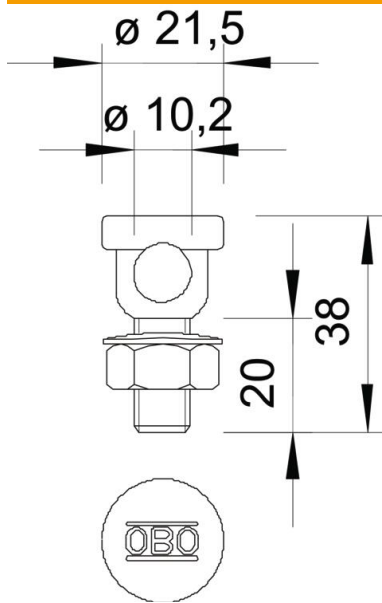

Technical data

Type of fastening screw	Miscellaneous
Type of connector	Connectors
Suitable for connection	Miscellaneous
Fit	Rd 8-10 mm
ROHS-conformant	yes
Intermediate plate	no