

Technical data sheet

Connector Rd 8–10 mm, single

Item number: 5304105



- With Fix-Kontakt clamping screw, nut and serrated washer
- With 10.2 mm drill hole
- With pre-mounted thrust piece made of die-cast zinc
- Corresponds to the requirements of VDE 0185-305 (IEC 62305)



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5304105
Type	5001 DIN-FT
Description 1	Connection terminal
Description 2	for round conductors
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	7.45 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2762 kg CO2e / 1 Piece


Technical data sheet

Connector Rd 8–10 mm, single

Item number: 5304105



Dimensions

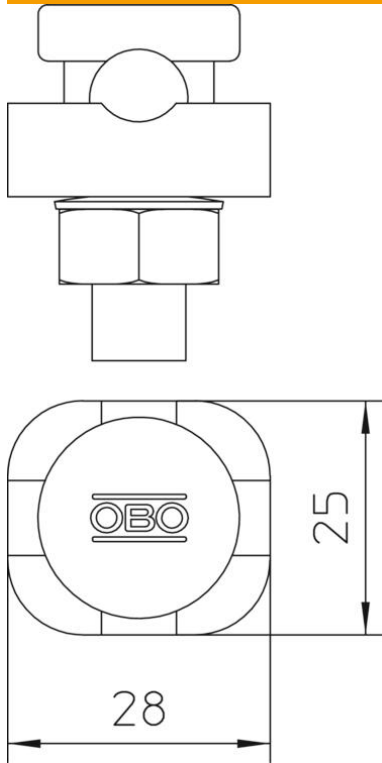

Length	38 mm
Width	28 mm
Height	25 mm

Technical data

Type of fastening screw	Clamping screw
Type of connector	Connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Miscellaneous
Fit	Rd 8-10 mm
ROHS-conformant	yes
Intermediate plate	no