


Technical data sheet

Connector Rd 8–10 mm, double

Item number: 5304202

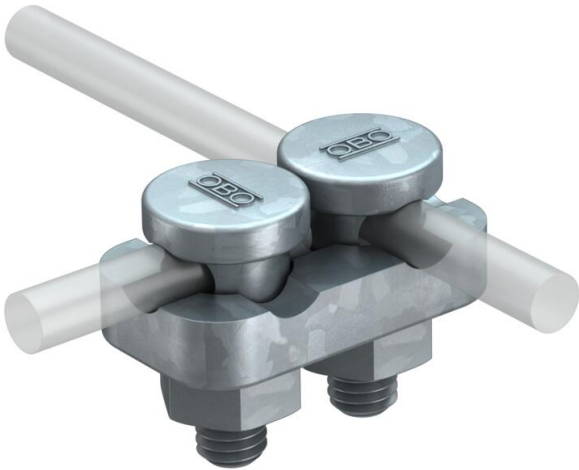

- With 2 fix contact clamping screws, nut and serrated washer
- Including pre-mounted connecting pressure piece, die-cast zinc or copper-plated die-cast zinc
- Conforms to the requirements according to DIN VDE 0185-305 (IEC 62305)



- St

Steel
- FT

Hot-dip galvanised

Master data	
Item number	5304202
Type	5002 DIN-FT
Description 1	Connection terminal
Description 2	for two round conductors
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	14.24 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,535 kg CO2e / 1 Piece


Technical data sheet

Connector Rd 8–10 mm, double

Item number: 5304202



Dimensions

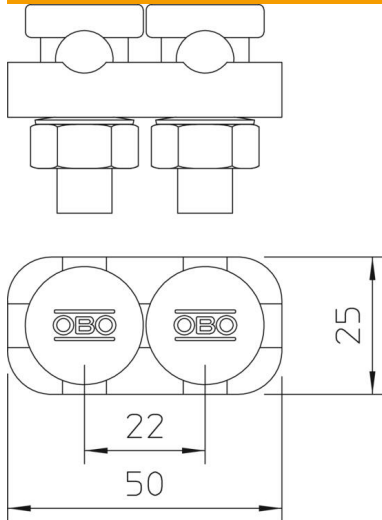

Technical data

Type of fastening screw	Clamping screw
Type of connector	Connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
ROHS-conformant	yes
Intermediate plate	no