

Technical data sheet

Vario quick connector Rd 6-8 / Rd 6-8 mm

Item number: 5311423



- For T, cross and parallel connectors
- Quick installation using hexagonal bolt M10 x 30, high-grade stainless steel
- Conforms to the requirements according to DIN VDE 0185-305 (IEC 62305)



A2 Stainless steel

Master data		
Item number	5311423	
Type	249 6-8 VA CH	
Description 1	Quick connector	
Description 2	Vario	
Manufacturer	OBO	
Dimension	40x40mm	
Material	Stainless steel	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	9.14 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,6777 kg CO2e / 1 Piece	


Technical data sheet

Vario quick connector Rd 6-8 / Rd 6-8 mm


Item number: 5311423



Dimensions

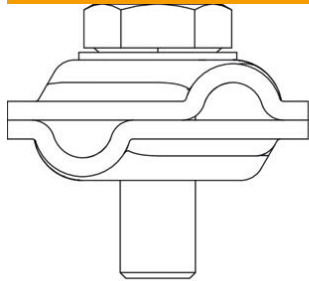

Dimension A 40 mm

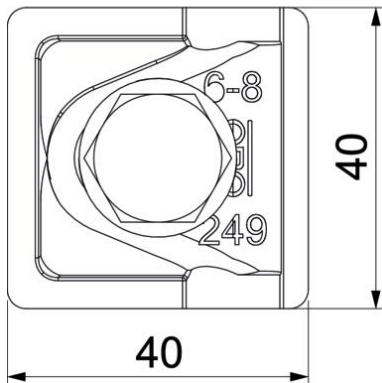

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Multipurpose connection clamp
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 6-8 / Rd 6-8
Fit	RD 6-8 / 6-8 mm
ROHS-conformant	yes
Intermediate plate	no