


Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 mm FT

Item number: 5312310

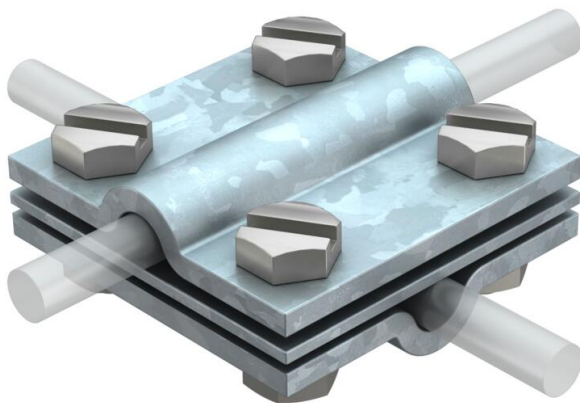

- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8-10 x Rd 8-10 / FL 30
- With adapter plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8 (F)



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5312310
Type	252 8-10 FT
Description 1	Cross-connectors
Manufacturer	OBO
Dimension	8-10mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	27.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6263 kg CO2e / 1 Piece

 
Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 mm FT


Item number: 5312310



Dimensions



Dimension A	60 mm
Dimension B	60 mm

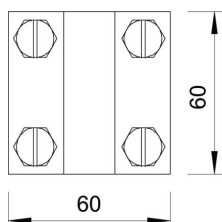

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
ROHS-conformant	yes
Intermediate plate	yes