


Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 x Rd 16 A4

Item number: 5312346

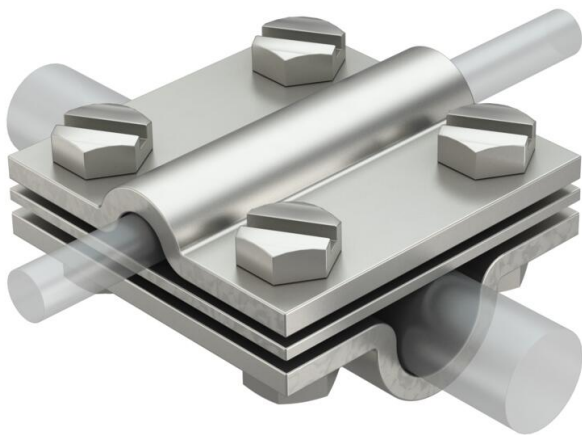

- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8-10 x Rd 16 / FL 30
- With adapter plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8



A4 Stainless steel

Master data

Item number	5312346
Type	252 8-10x16 V4A
Description 1	Cross-connectors
Manufacturer	OBO
Dimension	8-10mm
Material	Stainless steel 1.4571
Smallest sales unit	10
Unit of quantity	Piece
Weight	39 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,5643 kg CO2e / 1 Piece

 
Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 x Rd 16 A4


Item number: 5312346



Dimensions



Dimension A	60 mm
Dimension B	60 mm

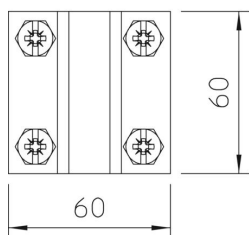

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8-10 / Rd 16
Fit	Rd 8-10 x 16 mm
ROHS-conformant	yes
Intermediate plate	yes