


Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 x Rd 16 Cu

Item number: 5312442



- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8–10 x Rd 16 / FL 30
- With adapter plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8 made of rust-proof stainless steel (A2)

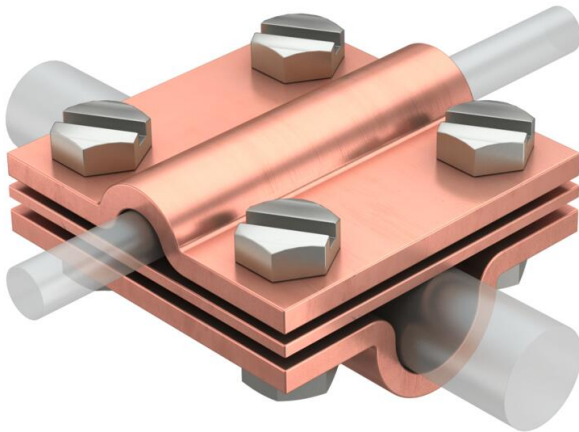

Cu

Copper

Master data

Item number	5312442
Type	252 8-10X16 CU
Description 1	Cross-connectors
Manufacturer	OBO
Dimension	8-10mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	43.985 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,2453 kg CO2e / 1 Piece

 
Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 x Rd 16 Cu


Item number: 5312442



Dimensions



Dimension A	60 mm
Dimension B	60 mm

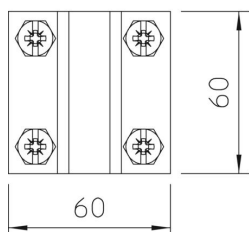

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8-10 / Rd 16
Fit	Rd 8-10 x 16 mm
Intermediate plate	yes