

Technical data sheet

Cross-connector round/round without intermediate plate A4

Item number: 5312582



- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8-10 x Rd 8-10 / FL 30
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8 (F)



A4 Stainless steel

Master data

Item number	5312582
Type	253 8-10 V4A
Description 1	Cross-connectors round/round
Description 2	no separator plate
Manufacturer	OBO
Dimension	60x60
Material	Stainless steel 1.4571/1.4404
Smallest sales unit	25
Unit of quantity	Piece
Weight	23.65 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,2047 kg CO2e / 1 Piece


 
Technical data sheet

Cross-connector round/round without intermediate plate A4

Item number: 5312582



Dimensions

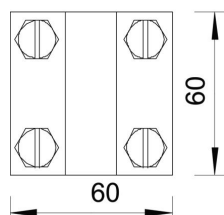

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
ROHS-conformant	yes
Intermediate plate	no