


Technical data sheet

Diagonal clamp with bolt FT

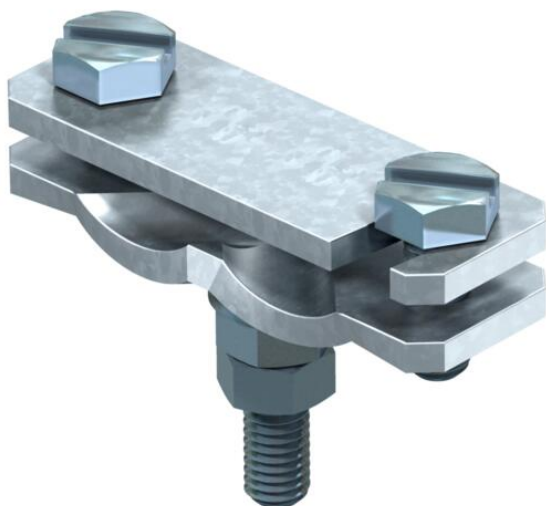

Item number: 5313066



- For reinforced steels Ø 6-22 mm and flat conductor 50 x 4
- Installed with bolts M10 x 25
- Simple installation with open slot
- With flange-welded bolts M10 x 40, inc. 2 washers and 2 nuts



St	Steel
F	Hot galvanised

Master data

Item number	5313066
Type	250 A-BO
Description 1	Diagonal clamp
Description 2	with flange-welded bolt
Manufacturer	OBO
Dimension	88x30x70
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	25
Unit of quantity	Piece
Weight	30.994 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5571 kg CO2e / 1 Piece


Technical data sheet

Diagonal clamp with bolt FT

Item number: 5313066



Dimensions

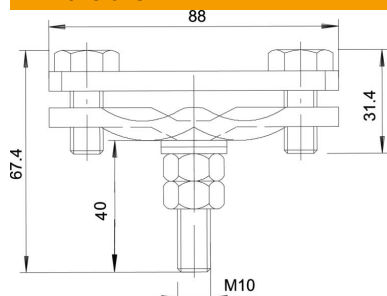

Dimension L 25 mm

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Connectors
Lightning current carrying capacity	H/100 kA
Flat conductor width, conductor 2, max.	5
Flat conductor width, conductor 2, min.	0
Suitable for connection	Miscellaneous
Fit	Rd 6-22/max. FL50 mm
Round conductor diameter, conductor 1, max.	22 mm
Round conductor diameter, conductor 1, min.	6 mm