

Technical data sheet

Terminal for FangFix system

Item number: 5403219



- FangFix terminal, VA for RD 8 mm
- Tested with H (0185 kA) to DIN EN 305-62305
- Round conductor installed on the air-termination rod with only one screw
- Suitable for Ø 16 mm pipe air-termination rods



A2 Stainless steel

Master data

Item number	5403219
Type	F-FIX-KL
Description 1	FangFix clamp
Manufacturer	OBO
Dimension	RD8
Material	Stainless steel 1.4301
Smallest sales unit	5
Unit of quantity	Piece
Weight	8.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6674 kg CO2e / 1 Piece


Technical data sheet

Terminal for FangFix system

Item number: 5403219



Dimensions

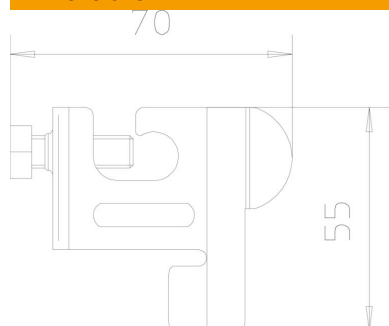

Width	70 mm
Height	55 mm

Technical data

Fit	Rd 8 mm
ROHS-conformant	yes