

# Technical data sheet

## Air-termination rod holder for sloping roof

Item number: 5403335



Stand system: rod holder for pitched roofs, for simple, quick and secure fastening of Ø 16 mm air-termination rods.

- System consists of a bracket made of V2A stainless steel
- Quick and easy mounting
- Adjustable angle
- In the case of high air-termination rods (> 1 m), additional fastening with insulated spaces is necessary

**A2** Stainless steel

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 5403335                  |
| Type                               | SD-Fix                   |
| Description 1                      | Rod holder               |
| Description 2                      | for sloping roofs        |
| Manufacturer                       | OBO                      |
| Dimension                          | Rd16                     |
| Material                           | Stainless steel 1.4301   |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 81 kg                    |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 5,9023 kg CO2e / 1 Piece |


# Technical data sheet

## Air-termination rod holder for sloping roof

Item number: 5403335



### Dimensions

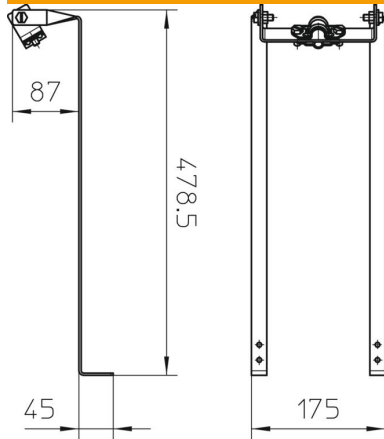

|                  |          |
|------------------|----------|
| Length           | 478.5 mm |
| Width            | 175 mm   |
| Height           | 87 mm    |
| Dimension d min. | 16 mm    |

### Technical data

|                       |                                   |
|-----------------------|-----------------------------------|
| Holder fastening type | Drill hole                        |
| Rod fastening type    | With screw clip                   |
| Fit                   | 16 mm                             |
| ROHS-conformant       | yes                               |
| Material of the base  | Stainless steel, rustproof 1.4301 |