

# Technical data sheet

Connection element for installation in the insulated interception rod isFang IN  
Item number: 5408019



- For the isCon® Basic and Professional cable
- Cable connection and routing in the insulated air-termination rod
- Screw-on termination
- Including heat-shrinkable sleeve and hexagonal wrench
- Tested to up to 150 kA (lightning protection class II)



**A2** Stainless steel

## Master data

|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 5408019                        |
| Type                               | isCon IN con 2                 |
| Description 1                      | Connection element             |
| Description 2                      | for isCon Basic + Pro internal |
| Manufacturer                       | OBO                            |
| Dimension                          | Ø20mm                          |
| Material                           | Stainless steel 1.4301         |
| Smallest sales unit                | 1                              |
| Unit of quantity                   | Piece                          |
| Weight                             | 27.8 kg                        |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,3077 kg CO2e / 1 Piece       |

# Technical data sheet

Connection element for installation in the insulated interception rod isFang IN


Item number: 5408019



## Dimensions

Dimension d min.

28 mm

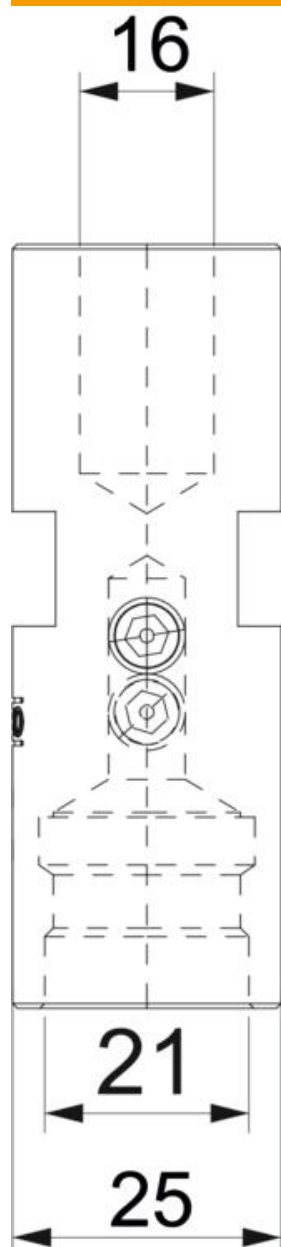

# Technical data sheet

Connection element for installation in the insulated interception rod isFang IN

Item number: 5408019



## Technical data

|                                     |               |
|-------------------------------------|---------------|
| Lightning current carrying capacity | H1/150 kA     |
| Suitable for connection             | Miscellaneous |
| Fit                                 | 20 mm         |
| ROHS-conformant                     | yes           |