

Technical data sheet

Fixed earthing terminal with double thread

Item number: 5420020



- For connecting to earthing systems, conductors and reinforcements
- Contact plate: Ø 79 mm from stainless steel, rustproof (V4A)
- Double thread M10/M12
- Including plastic cover for easy installation



A4 Stainless steel

Master data

Item number	5420020
Type	205 DG V4A
Description 1	Earthing fixed point
Description 2	with double thread
Manufacturer	OBO
Dimension	M10/M12
Material	Stainless steel 1.4404
Smallest sales unit	10
Unit of quantity	Piece
Weight	14.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0155 kg CO2e / 1 Piece


Technical data sheet

Fixed earthing terminal with double thread

Item number: 5420020



Dimensions

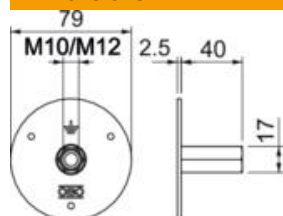

Length	180 mm
--------	--------

Technical data

Lightning current carrying capacity	H/100 kA
Diameter of the contact plate	79 mm
Thread	M10/M12
Short-circuit current (50 HZ)(1 s; $\leq 300^{\circ}\text{C}$)	6.2 kA
ROHS-conformant	yes