

Technical data sheet

Fixed earthing terminal with connection bolt and double thread A4

Item number: 5420022



- For connecting to earthing systems, conductors and reinforcements
- Contact plate: Ø 79 mm from stainless steel, rustproof (V4A)
- With M10 and M12 thread
- Including plastic cover for easy installation
- With connection bolt: Ø 10 mm (V4A)




A4 Stainless steel

Master data

Item number	5420022
Type	205 DG L180 V4A
Description 1	Earthing fixed point with axis
Description 2	and double thread
Manufacturer	OBO
Dimension	M10/M12
Material	Stainless steel 1.4404
Smallest sales unit	10
Unit of quantity	Piece
Weight	23.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,4557 kg CO2e / 1 Piece

Dimensions

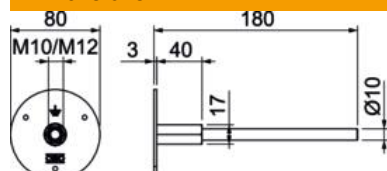

Length	180 mm
--------	--------

Technical data sheet

Fixed earthing terminal with connection bolt and double thread A4

Item number: 5420022



Technical data

Diameter of the connection bolt	10 mm
Lightning current carrying capacity	H/100 kA
Diameter of the contact plate	79 mm
Thread	M10/M12
Short-circuit current (50 HZ)(1 s; ≤300°C)	3.3 kA
Material of the connection bolt	Stainless steel, rustproof (V4A)