

Technical data sheet

Beam clamp

Item number: 6003850



Beam clamp for fastening the mesh bracket, type GW 40 80 to steel girders. When selecting the beam clamp, please take the flange thickness of the steel girder into account.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6003850
Type	KL 20 FT
Description 1	Hold-down clamp
Manufacturer	OBO
Dimension	20mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	19 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4546 kg CO2e / 1 Piece


Technical data sheet

Beam clamp

Item number: 6003850



Dimensions

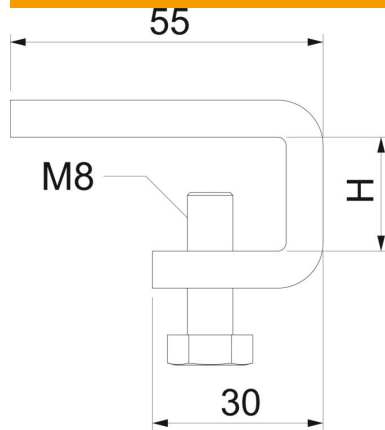

Height	20 mm
--------	-------

Technical data

Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Hole diameter	8 mm
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector