

Technical data sheet

Beam clamp, vertical BFK 132 A2

Item number: 6003871



Beam clamp for clamping on the steel girder.
The cable support system attached to the beam clamp runs vertically.



- A2

Stainless steel
- 2B

Bright, treated

Master data	
Item number	6003871
Type	BFK 132 58 A2
Description 1	Clamping piece
Description 2	for max. supp. thickness 20 mm
Manufacturer	OBO
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	38 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,0367 kg CO2e / 1 Piece


Technical data sheet

Beam clamp, vertical BFK 132 A2

Item number: 6003871



Dimensions

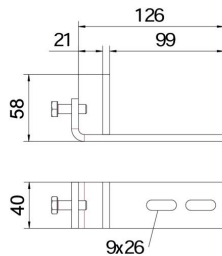

Width	132 mm
Height	20 mm
Dimension B	132 mm
Dimension b	99 mm
Dimension B1	99 mm

Technical data

Version for	Miscellaneous
Suitable for profile shapes	C profile
ROHS-conformant	yes