

Technical data sheet

Beam clamp, vertical BFK 166 A2

Item number: 6003877



Beam clamp for clamping on the steel girder.
The cable support system attached to the beam clamp runs vertically.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6003877
Type	BFK 166 58 20 A2
Description 1	Clamping piece
Description 2	for max. supp. thickness 20 mm
Manufacturer	OBO
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	46 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,3569 kg CO2e / 1 Piece


Technical data sheet

Beam clamp, vertical BFK 166 A2

Item number: 6003877



Dimensions

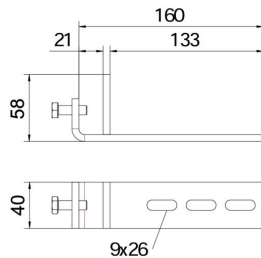

Width	166 mm
Height	20 mm
Dimension B	166 mm
Dimension b	133 mm
Dimension B1	133 mm

Technical data

Version for	Miscellaneous
Suitable for profile shapes	C profile
ROHS-conformant	yes