


Technical data sheet

Beam clamp with pressure plate, horizontal BFK 153 FT

Item number: 6003885



Beam clamp with pressure plate for clamping on the steel girder.
The cable support system attached to the beam clamp runs horizontally.

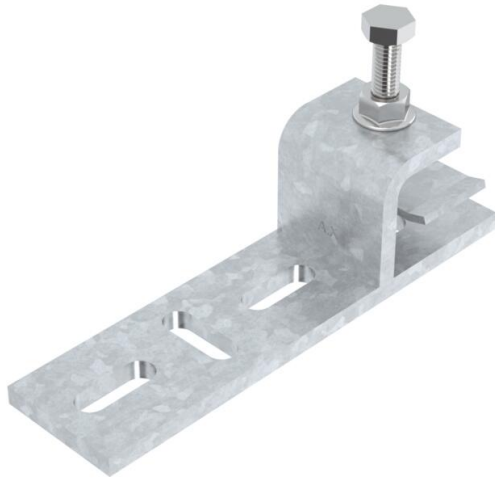

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6003885
Type	BFKD 153 44 FT
Description 1	Clamping piece
Description 2	for max. supp. thickness 28 mm
Manufacturer	OBO
Dimension	153x40x44mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	41.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0676 kg CO2e / 1 Piece


Technical data sheet

Beam clamp with pressure plate, horizontal BFK 153 FT

Item number: 6003885



Dimensions

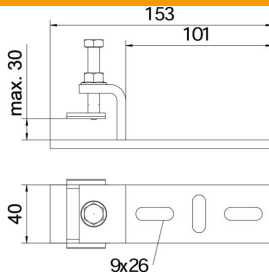

Width	153 mm
Height	28 mm
Dimension B	153 mm
Dimension b	101 mm
Dimension B1	101 mm

Technical data

Version for	Miscellaneous
Maintain electrical functions	no
Suitable for profile shapes	C profile
Material thickness	6 mm
With screw accessories	no
ROHS-conformant	yes
Adjustable	yes