

Technical data sheet

Beam clamp with pressure plate, horizontal BFK 153 A2

Item number: 6003887



Fastening clamp with pressure plate for clamping on the steel girder.
The cable support system attached to the fastening clamp runs horizontally.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6003887
Type	BFKD 153 44 A2
Description 1	Clamping piece
Description 2	for max. supp. thickness 28 mm
Manufacturer	OBO
Dimension	153x40x44mm
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	42.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,4909 kg CO2e / 1 Piece


Technical data sheet

Beam clamp with pressure plate, horizontal BFK 153 A2

Item number: 6003887



Dimensions

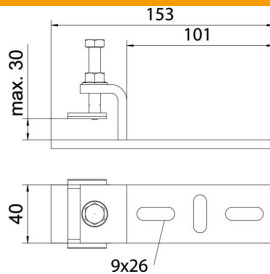

Width	153 mm
Height	28 mm
Dimension B	153 mm
Dimension b	101 mm
Dimension B1	101 mm

Technical data

Version for	Miscellaneous
Maintain electrical functions	no
Suitable for profile shapes	C profile
Material thickness	6 mm
With screw accessories	no
ROHS-conformant	yes
Adjustable	yes