

Technical data sheet

Centre suspension mesh cable tray FT

Item number: 6015224



Two-part centre suspension of mesh cable trays.
When filling with cables, please ensure an even distribution. The maximum recommended mesh cable tray width is 200 mm.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6015224
Type	GMA M6 FT
Description 1	Centre suspension
Description 2	for threaded rod M6
Manufacturer	OBO
Dimension	60x40
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	8.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,197 kg CO2e / 1 Piece



Technical data sheet

Centre suspension mesh cable tray FT

Item number: 6015224



Dimensions

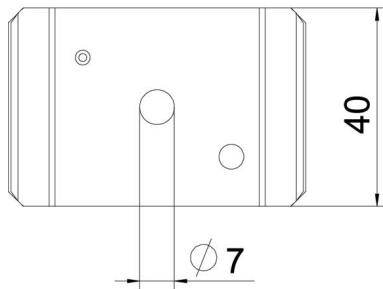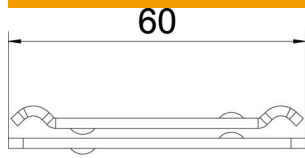

Length	65 mm
Width	40 mm
Height	6.5 mm

Technical data

Version for	Suspended
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Hole diameter	7 mm
ROHS-conformant	yes
Adjustable	no