

Technical data sheet

Quick connector

Item number: 6016545



Quick connector for screwless straight connection of mesh cable trays without special tools, for mesh cable trays up to a width of 150 mm.
When selecting the connector, please take the appropriate wire thickness of the mesh cable tray into account.
Figure: Positioning and quantity of mesh cable tray connectors.

50–150 mm = 2 units




St Steel

DD Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	6016545
Type	GRS 3.9 DD
Description 1	Quick connector
Description 2	for mesh cable tray
Manufacturer	OBO
Dimension	d 3,9mm
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	50
Unit of quantity	Piece
Weight	2.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,111 kg CO2e / 1 Piece

Dimensions

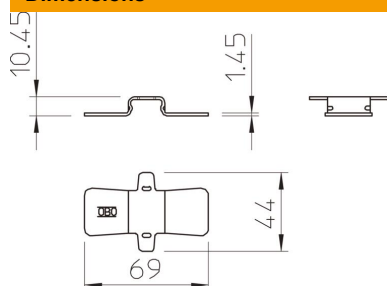

Dimension	69 x 44
Length	69 mm
Width	44 mm
Width	1.73 in
Height	11 mm
Height	0.43 in
Plate thickness	1.45 mm

Technical data sheet

Quick connector

Item number: 6016545



Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screwless connector