

Technical data sheet

Corner connector A4

Item number: 6016764



Corner connector for the creation of mesh cable tray bend elements.
Including FRS M6 x 12 bolt with flange nut



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	6016764	
Type	GEV 36 A4	
Description 1	Corner connector	
Description 2	for mesh cable tray	
Manufacturer	OBO	
Colour	stainless steel	
Material	Stainless steel 1.4401	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	3.04 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1819 kg CO2e / 1 Piece	


Technical data sheet

Corner connector A4

Item number: 6016764



Dimensions

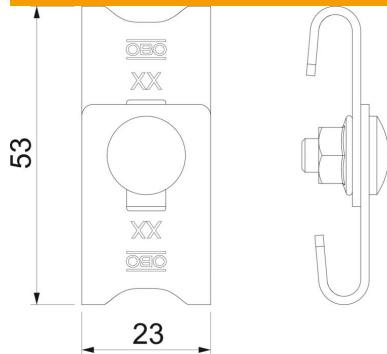

Dimension	42-54 x 23
Length	56 mm
Width	23 mm
Width	0.91 in
Height	16 mm
Height	0.63 in

Technical data

Version for	Corner connector
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Suitable for mesh cable tray wire, max.	4.9 mm
Suitable for mesh cable tray wire, min.	3.9 mm
Rustproof steel, pickled	no
Connection type	Screw connector