

Technical data sheet

Cover clip for WDK trunking, trunking width 60 mm

Item number: 6022995



Cover clip for better and easier laying of lines in the WDK trunking.
The cover clip can be moved along the entire length of the trunking.
The cover clip is locked on one side and moved forward. This provides an opening of 30°, making cable routing very easy.




PVC Polyvinylchloride

Master data

Item number	6022995
Type	2370 60
Description 1	Cover fixing device
Manufacturer	OBO
Dimension	60mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0235 kg CO2e / 1 Piece

Dimensions

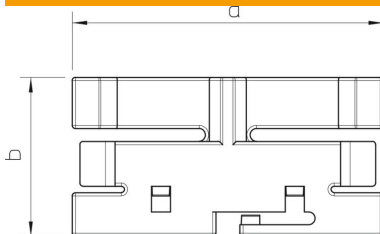

Length	24.8 mm
Width	48.8 mm
Dimension a	48.8 mm
Dimension b	24.8 mm

Technical data sheet

Cover clip for WDK trunking, trunking width 60 mm

Item number: 6022995



Technical data

Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
With equipotential bonding	no
Cover width	60 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C