

Technical data sheet

Partition for WDK trunking, trunking height 40 mm

Item number: 6023096



Partition to divide the WDK trunking, with 40 mm trunking height, and various ISS service poles for the installation of different voltage levels.
The partitions are pinned on the connectors in the base.



PVC Polyvinylchloride

Master data

Item number	6023096
Type	2371 40
Description 1	Partition
Manufacturer	OBO
Dimension	40x2000mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	13.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,3138 kg CO2e / 1 Meter


Technical data sheet

Partition for WDK trunking, trunking height 40 mm

Item number: 6023096



Dimensions

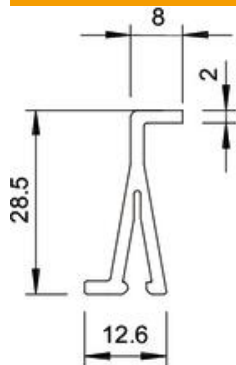

Length	2,000 mm
Width	12.6 mm
Height	28.5 mm

Technical data

Version for	Single
Fastening type	Plug-in
Halogen-free	no
Trunking depth	40 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C