

Technical data sheet

Partition for WDK trunking, trunking height 60 mm

Item number: 6023118



Partition to divide the WDK trunking, with 60 mm trunking height for the installation of different voltage levels.
The partitions are pinned on the connectors in the base.



PVC Polyvinylchloride

Master data

Item number	6023118
Type	2371 60
Description 1	Partition
Manufacturer	OBO
Dimension	60x2000mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	17 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,5121 kg CO2e / 1 Meter


Technical data sheet

Partition for WDK trunking, trunking height 60 mm

Item number: 6023118



Dimensions

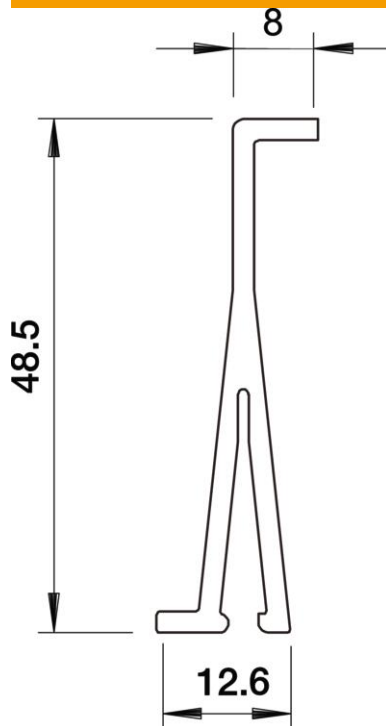

Length	2,000 mm
Width	12.6 mm
Height	48.5 mm

Technical data

Version for	Single
Fastening type	Plug-in
Halogen-free	no
Trunking depth	60 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C