

Technical data sheet

Partition for WDK trunking, trunking height 80 mm

Item number: 6026982



Partition to divide the WDK trunking, with 80 mm trunking height for the installation of different voltage levels.

The partitions are pinned on the connectors in the base.



PVC Polyvinylchloride

Master data		
Item number	6026982	
Type	2371 80	
Description 1	Partition	
Manufacturer	OBO	
Dimension	80x2000mm	
Colour	Light grey; RAL 7035	
Material	Polyvinylchloride	
Smallest sales unit	2	
Unit of quantity	Metre	
Weight	33 kg	
Weight unit	kg/100 m	
CO2 Footprint (GWP) Cradle-to-Gate	0,5987 kg CO2e / 1 Meter	


Technical data sheet

Partition for WDK trunking, trunking height 80 mm

Item number: 6026982



Dimensions

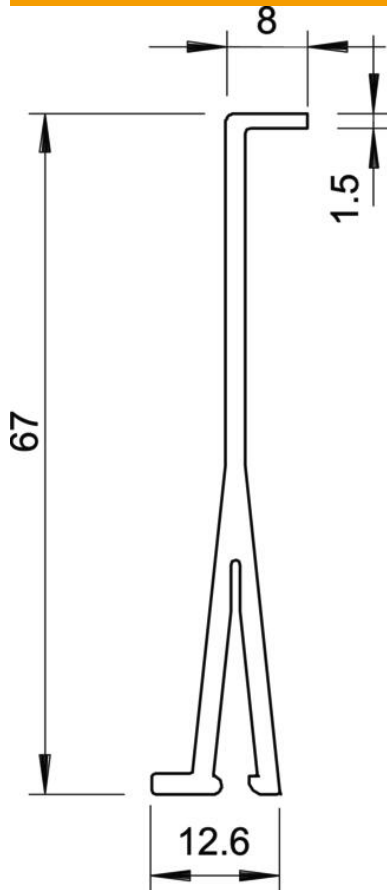

Length	2,000 mm
Width	12.6 mm
Height	67 mm

Technical data

Version for	Single
Fastening type	Plug-in
Halogen-free	no
Trunking depth	80 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C