

Technical data sheet

Partition for WDK trunking, trunking height 100 mm

Item number: 6026990



Partition to divide the WDK trunking, with 100 mm trunking height for the installation of different voltage levels.
The partitions are pinned on the connectors in the base.



PVC Polyvinylchloride

Master data

Item number	6026990
Type	2371 100
Description 1	Partition
Manufacturer	OBO
Dimension	100x2000mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	40 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,7101 kg CO2e / 1 Meter


Technical data sheet

Partition for WDK trunking, trunking height 100 mm

Item number: 6026990



Dimensions

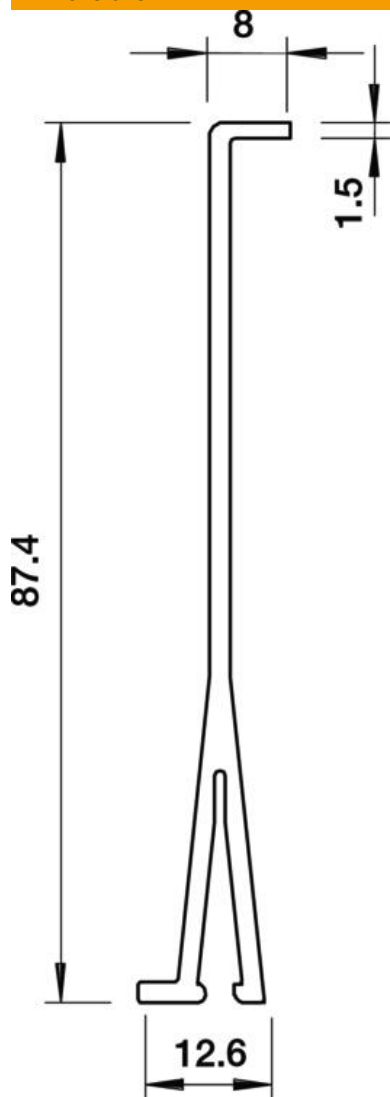

Length	2,000 mm
Width	12.6 mm
Height	87.4 mm

Technical data sheet

Partition for WDK trunking, trunking height 100 mm

Item number: 6026990



Technical data

Version for	Single
Fastening type	Plug-in
Halogen-free	no
Trunking depth	100 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C