

Technical data sheet

Cover, T piece 100 A2

Item number: 6038661



Cover for T piece fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights.
The cover can be used with fittings of all side heights.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6038661
Type	RTD 100 A2
Description 1	Cover
Description 2	for T piece
Manufacturer	OBO
Dimension	B100mm
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	20 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,8253 kg CO2e / 1 Piece


Technical data sheet

Cover, T piece 100 A2

Item number: 6038661



Dimensions

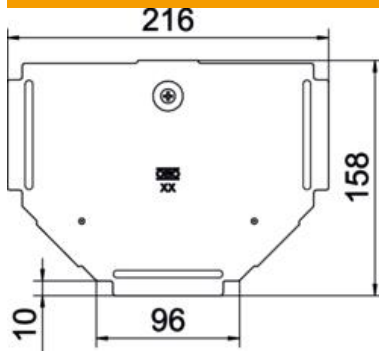

Width	100 mm
Plate thickness	0.75 mm
Dimension B	100 mm

Technical data

Number of turn buckles	1 St.
Fastening type	Sash lock
Suitable for cable ladder	no
Suitable for cable tray	yes
Material thickness	0.75 mm
ROHS-conformant	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no