


Technical data sheet

90° Magic bend 60 FS

Item number: 6041136



90° bend with quick connector system. For all cable tray types of 60 mm side height.

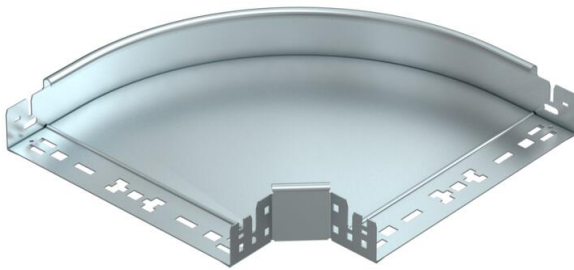

St	Steel
FS	Strip galvanised

Master data

Item number	6041136
Type	RBM 90 630 FS
Description 1	90° bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x300
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	192.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	6,5163 kg CO2e / 1 Piece


Technical data sheet

90° Magic bend 60 FS

Item number: 6041136



Dimensions

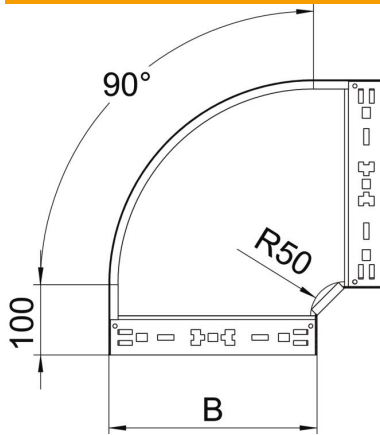

Width	300 mm
Width	12 in
Height	60 mm
Height	2 in
Plate thickness	1.25 mm
Dimension B	300 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	yes
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
ROHS-conformant	yes
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Click fastening