


Technical data sheet

90° Magic bend 60 FT

Item number: 6041154



90° bend with quick connector system. For all cable tray types of 60 mm side height.

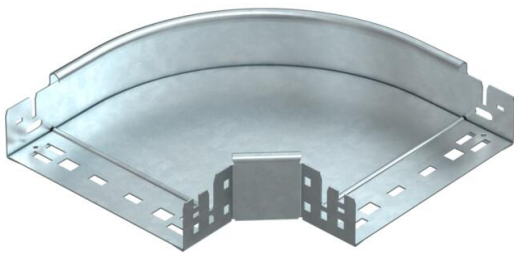

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6041154
Type	RBM 90 620 FT
Description 1	90° bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x200
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	131.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,4903 kg CO2e / 1 Piece

Technical data sheet

90° Magic bend 60 FT

Item number: 6041154



Dimensions



Width	200 mm
Width	8 in
Height	60 mm
Height	2 in
Plate thickness	1.25 mm
Dimension B	200 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Type	Bend, rigid
Maintain electrical functions	yes
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
ROHS-conformant	yes
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Click fastening