


Technical data sheet

Add-on tee 110 FS

Item number: 6042153

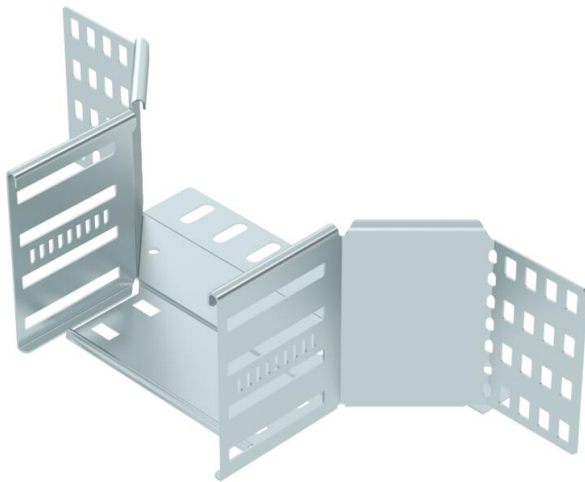

Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used in indoor areas. Fastening material must be ordered separately.



St	Steel
FS	Strip galvanised

Master data

Item number	6042153
Type	RAA 115 FS
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	110x150
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	55.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,0554 kg CO2e / 1 Piece


Technical data sheet

Add-on tee 110 FS

Item number: 6042153



Dimensions

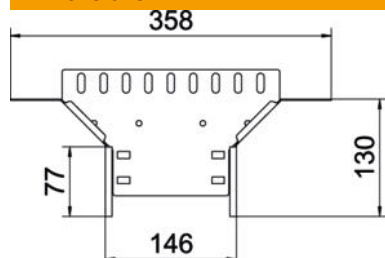

Width	150 mm
Height	110 mm
Plate thickness	0.8 mm
Dimension B	150 mm

Technical data

Departing width	150 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	0.8 mm
NATO hole pattern	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	18 St.
Rail thickness	1.25 mm