


Technical data sheet

Add-on tee 110 A2

Item number: 6042345

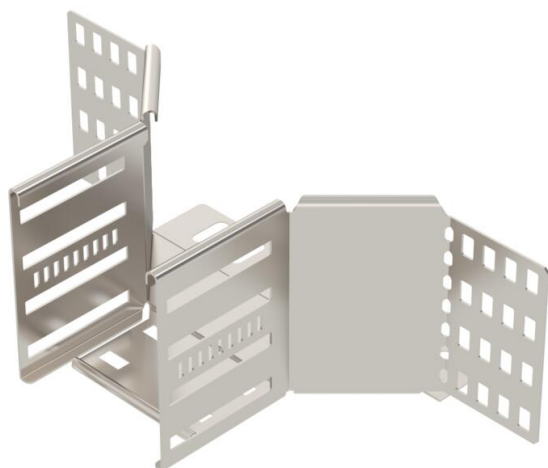

Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6042345
Type	RAA 110 A2
Description 1	Add-on tee
Description 2	for cable tray
Manufacturer	OBO
Dimension	110x100
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	50.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,4803 kg CO2e / 1 Piece


Technical data sheet

Add-on tee 110 A2

Item number: 6042345



Dimensions

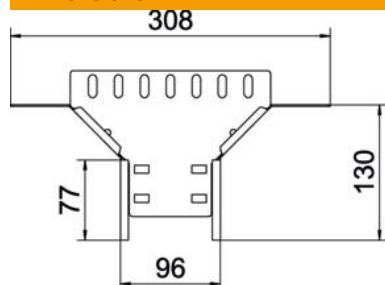

Width	100 mm
Height	110 mm
Plate thickness	0.8 mm
Dimension B	100 mm

Technical data

Departing width	100 mm
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	0.8 mm
NATO hole pattern	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	18 St.
Rail thickness	1.25 mm