


Technical data sheet

Straight and angle connector 60 FT

Item number: 6042910



Angle connector for cable trays with a side height of 60 mm.
Including appropriate fastening material.

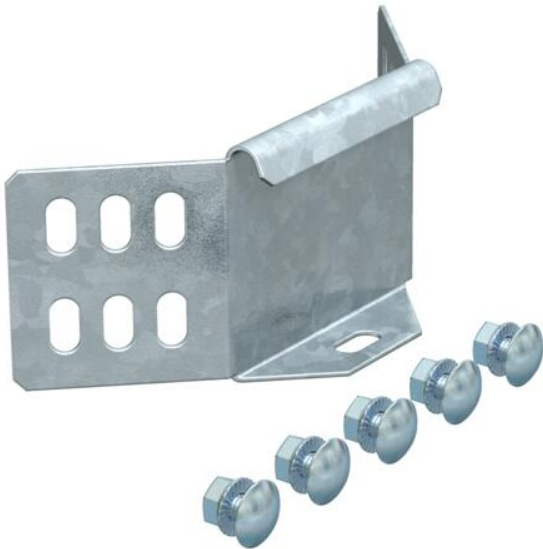

St

Steel

FT

Hot-dip galvanised

Master data

Item number	6042910
Type	WKV 60 FT
Description 1	Angle connector
Description 2	for cable tray
Manufacturer	OBO
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	5
Unit of quantity	Piece
Weight	15.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4493 kg CO2e / 1 Piece


Technical data sheet

Straight and angle connector 60 FT

Item number: 6042910



Dimensions

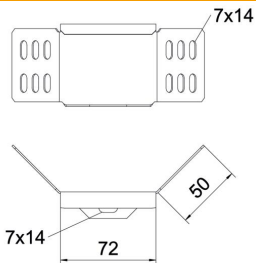

Length	72 mm
Width	50 mm
Height	62 mm
Height	2 in
Plate thickness	1.25 mm

Technical data

Version for	Angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector