


Technical data sheet

90° bend 60, black

Item number: 6043264



90° bend, horizontal, fitting for all cable tray types of 60 mm side height. Black coated.

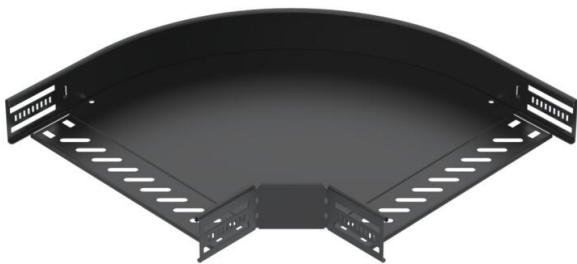

- St** Steel
- P135** PES135 - Polyester

Master data		
Item number	6043264	
Type	RB 90 630 FSK SW	
Description 1	90° bend	
Description 2	for cable tray, horizontal	
Manufacturer	OBO	
Dimension	60x300	
Colour	Jet black; RAL 9005	
Material	Steel	
Surface	PES135 - Polyester	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	148.2 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1874 kg CO2e / 1 Piece	


Technical data sheet

90° bend 60, black

Item number: 6043264



Dimensions

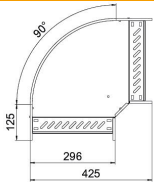

Width	300 mm
Height	60 mm
Dimension B	300 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Type	Bend, rigid
Maintain electrical functions	yes
Material thickness, floor plate	0.8 mm
With cover	no
Mounting perforation in base	no
Change of direction	Horizontal
ROHS-conformant	yes
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Recommended quantity of bolts	14 St.
Rail thickness	1.25 mm