

Technical data sheet

A4 suspension bracket 50

Item number: 6066508



Suspension bracket for chain or steel wire tensioning rope fastening of the luminaire support rail, type LTS 50, and the AZ small duct, type AZK 50.



- A4 Stainless steel
- 2B Bright, treated

Master data	
Item number	6066508
Type	AHB 50 D4 A4
Description 1	Suspension clamp
Description 2	for AZK 50 and LTS 50
Manufacturer	OBO
Colour	stainless steel
Material	Stainless steel 1.4401
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.985 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0981 kg CO2e / 1 Piece


Technical data sheet

A4 suspension bracket 50

Item number: 6066508



Dimensions

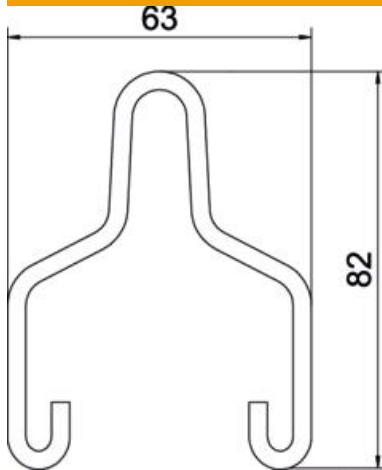

Width	62.8 mm
Height	82.3 mm

Technical data

F in kN	0.35 kN
Maintain electrical functions	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Hinged	no
Adjustable	no