

Technical data sheet

Straight and angle connector 50 FT

Item number: 6066550



Straight and angle connector for connection of AZ channels.
An adjustable connector can be created using two straight and angle connectors.
Scope of delivery including bolts with combination nuts.




St Steel

FT Hot-dip galvanised

Master data

Item number	6066550
Type	VF AZK FT
Description 1	Straight and angle connector
Description 2	for AZ duct
Manufacturer	OBO
Dimension	45x100
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	7.656 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1992 kg CO2e / 1 Piece

Dimensions

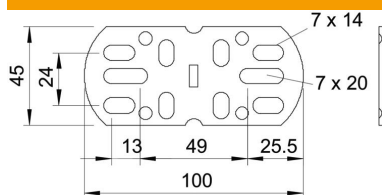

Length	100 mm
Width	100 mm
Height	45 mm
Plate thickness	1.5 mm

Technical data sheet

Straight and angle connector 50 FT

Item number: 6066550



Technical data

Version for	Straight and angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	50 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector