

Technical data sheet

Straight connector 60 FSK, black

Item number: 6067097



Straight connector for the straight connection of cable trays and fittings with a side height of 60 mm. Powder-coated in jet black (RAL 9005) Including appropriate fastening material.



St

Steel

P135

PES135 - Polyester

Master data

Item number	6067097
Type	RLVK 60 FSK SW
Description 1	Straight connector
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x100
Colour	Jet black; RAL 9005
Material	Steel
Surface	PES135 - Polyester
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	9.88 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0092 kg CO2e / 1 Piece


Technical data sheet

Straight connector 60 FSK, black

Item number: 6067097



Dimensions

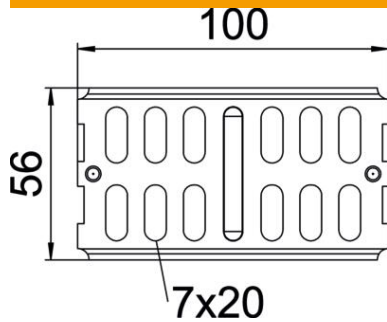

Dimension	200 x 56
Length	100 mm
Width	3.5 mm
Height	56 mm
Plate thickness	2 mm

Technical data

Quantity of bolts	4 St.
Version for	Straight connector
Maintain electrical functions	yes
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector
Wide-span version	no