


Technical data sheet

Straight and angle connector 60 FS

Item number: 6067115

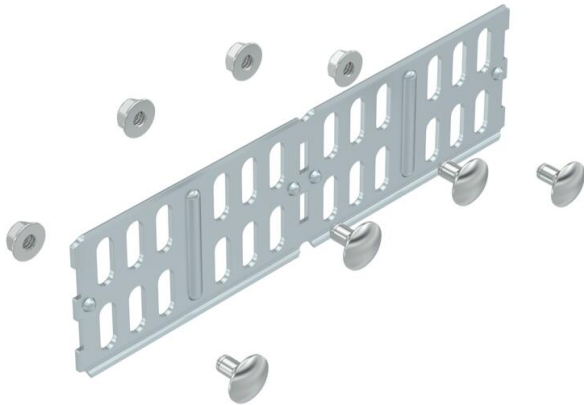

Straight and angle connector for cable trays and fittings with a side height of 60 mm.
Including appropriate fastening material.
Including truss-head bolts and combination nuts.



St	Steel
FS	Strip galvanised

Master data

Item number	6067115
Type	RWVL 60 FS
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	60x200
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	10
Unit of quantity	Piece
Weight	16.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4819 kg CO2e / 1 Piece


Technical data sheet

Straight and angle connector 60 FS

Item number: 6067115



Dimensions

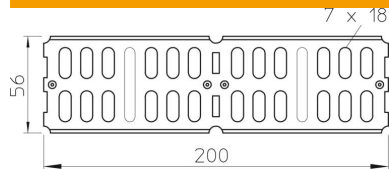

Dimension	200 x 56
Length	200 mm
Width	4 mm
Height	60 mm
Height	2 in
Plate thickness	2 mm

Technical data

Version for	Angle connector
Maintain electrical functions	yes
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector