


Technical data sheet

Straight and angle connector

Item number: 6067123

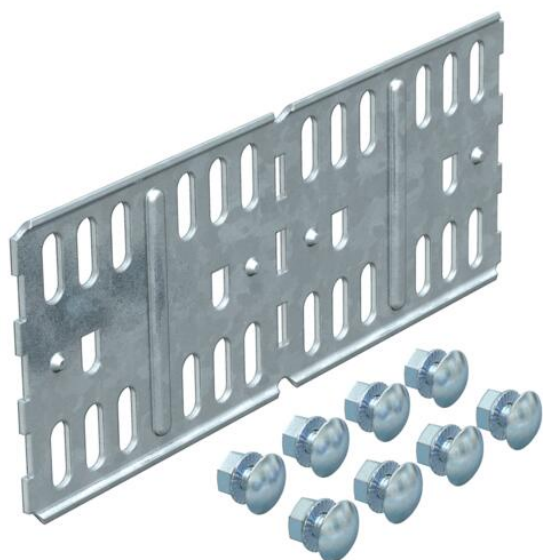

Straight and angle connector for cable trays and fittings with a side height of 85 mm.
Including appropriate fastening material.



St	Steel
FS	Strip galvanised

Master data

Item number	6067123
Type	RLVL 85 FS
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	85x200
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	10
Unit of quantity	Piece
Weight	27.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7229 kg CO2e / 1 Piece


Technical data sheet

Straight and angle connector

Item number: 6067123



Dimensions

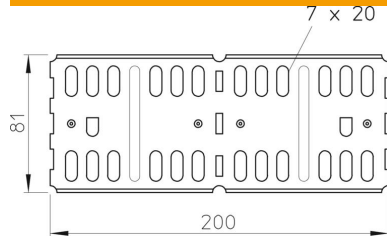

Dimension	200 x 81
Length	200 mm
Width	4 mm
Height	85 mm
Height	3 in
Plate thickness	2 mm

Technical data

Version for	Straight and angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	85 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector