


Technical data sheet

Straight and angle connector FT

Item number: 6067328

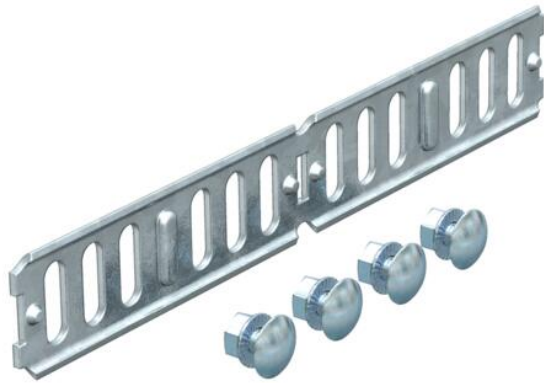

Straight and angle connector for cable trays and fittings with a side height of 35 mm.
Including appropriate fastening material.



St

Steel


FT

Hot-dip galvanised

Master data

Item number	6067328
Type	RWVL 35 FT
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	35x200
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	10.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2773 kg CO2e / 1 Piece

 Dimensions



Dimension	200 x 31
Length	200 mm
Width	4 mm
Height	31 mm
Height	1 in
Plate thickness	2 mm

Technical data sheet

Straight and angle connector FT

Item number: 6067328



Technical data

Version for	Angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	35 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector