


Technical data sheet

Straight and angle connector 60 FSK, black

Item number: 6067624



Straight and angle connector for cable trays and fittings with a 60 mm side height. Powder-coated in jet black (RAL 9005) Including appropriate fastening material.

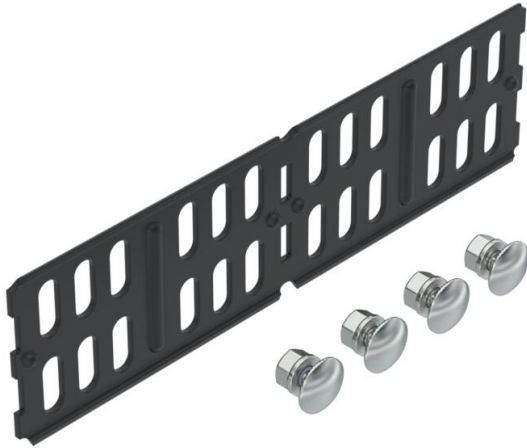

St	Steel
P135	PES135 - Polyester

Master data

Item number	6067624
Type	RWVL 60 FSK SW
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	60x200
Colour	Jet black; RAL 9005
Material	Steel
Surface	PES135 - Polyester
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	16.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0166 kg CO2e / 1 Piece

 
Technical data sheet

Straight and angle connector 60 FSK, black

Item number: 6067624



Dimensions



Dimension	254 x 56
Length	254 mm
Width	16 mm
Height	60 mm
Plate thickness	2 mm

Technical data

Quantity of bolts	4 St.
Version for	Angle connector
Maintain electrical functions	yes
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector
Wide-span version	no