


Technical data sheet

Straight and angle connector 60 A2

Item number: 6067662



Straight and angle connector for cable trays and fittings with a side height of 60 mm.
Including appropriate fastening material.

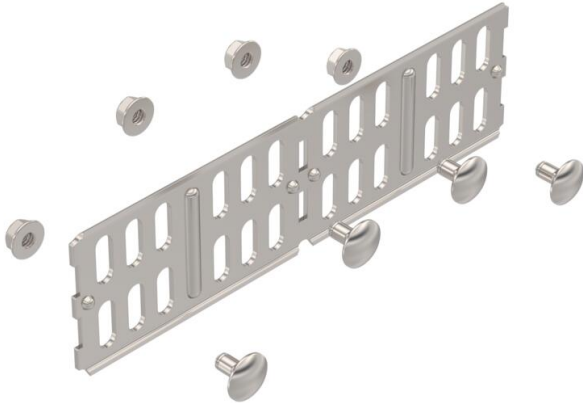

A2 Stainless steel

2B Bright, treated

Master data

Item number	6067662
Type	RWVL 60 A2
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	60x200
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	16.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0355 kg CO2e / 1 Piece


Technical data sheet

Straight and angle connector 60 A2

Item number: 6067662



Dimensions

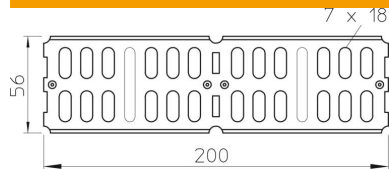

Dimension	200 x 56
Length	200 mm
Width	4 mm
Height	60 mm
Height	2 in
Plate thickness	2 mm

Technical data

Version for	Angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector