


Technical data sheet

Straight and angle connector 110 FT

Item number: 6067913



Straight and angle connector for cable trays and fittings with a side height of 110 mm.
Including appropriate fastening material.

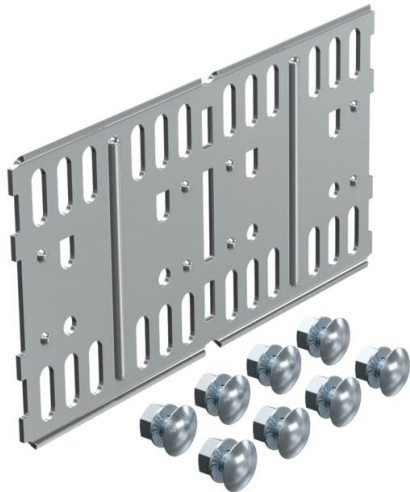

St

Steel

FT

Hot-dip galvanised

Master data

Item number	6067913
Type	RLVL 110 FT
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	110x200
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	32.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8547 kg CO2e / 1 Piece


Technical data sheet

Straight and angle connector 110 FT

Item number: 6067913



Dimensions

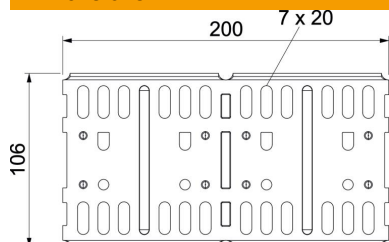

Length	200 mm
Width	4 mm
Height	110 mm
Height	4 in

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	110 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector