


Technical data sheet

Cover, unperforated DD

Item number: 6080239

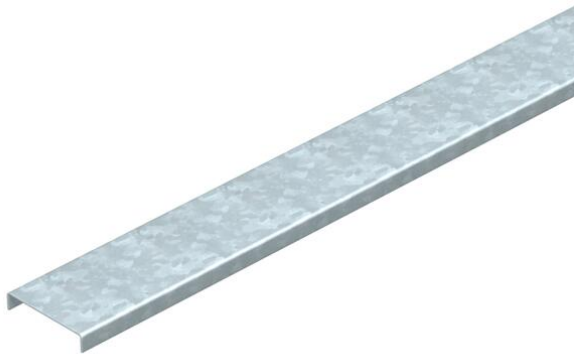

Cover without turn buckles for AZ small duct.
To fasten the cover, use the cover clamp, type DKU.



St

Steel

DD

Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	6080239
Type	AZDU 100 DD
Description 1	Unperforated cover
Description 2	for AZ small duct
Manufacturer	OBO
Dimension	103x3000
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	93.433 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	2,1344 kg CO2e / 1 Meter


Technical data sheet

Cover, unperforated DD

Item number: 6080239



Dimensions

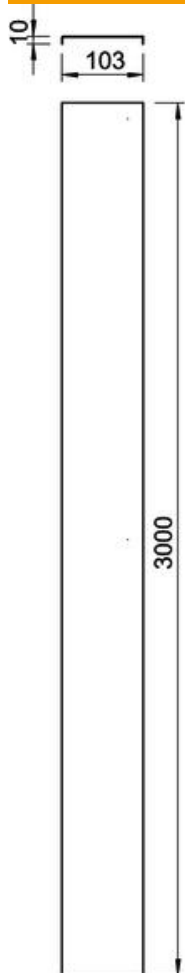

Length	3,000 mm
Width	103 mm
Height	10 mm
Plate thickness	1 mm
Dimension H	10 mm

Technical data

Number of turn buckles	6 St.
Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
ROHS-conformant	yes
Rustproof steel, pickled	no