

Technical data sheet

Cover for center suspension threaded rod FS

Item number: 6080979



Perforated cover, for threaded rod mounting, for AZ small duct.

To fasten the cover, the cover clamp DKU is required.



St	Steel
FS	Strip galvanised

Master data

Item number	6080979
Type	AZDG 100 FS
Description 1	Perforated cover
Description 2	hole diameter 12 mm
Manufacturer	OBO
Dimension	103x3000
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	93.23 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	2,1431 kg CO2e / 1 Meter


Technical data sheet

Cover for center suspension threaded rod FS

Item number: 6080979



Dimensions

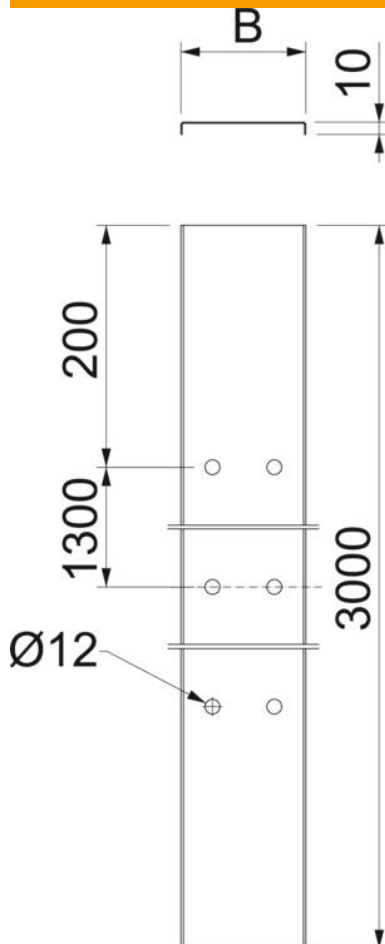

Length	3,000 mm
Width	103 mm
Height	10 mm
Plate thickness	1 mm
Dimension B	103 mm
Dimension H	10 mm

Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
ROHS-conformant	yes
Rustproof steel, pickled	no