


Technical data sheet

Adjustable connector 200 FT

Item number: 6083210

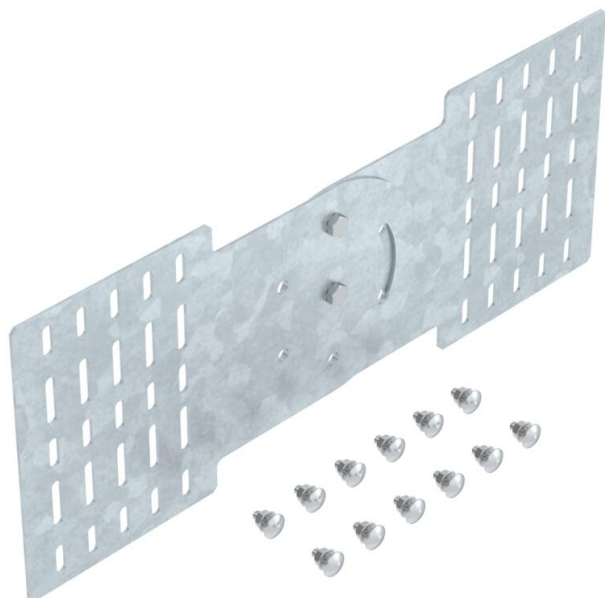

Adjustable connector for vertically rounded connections of cable trays (FT) with a side height of 200 mm.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6083210
Type	GVM 200 FT
Description 1	Adjustable connector
Description 2	for MFR cable tray
Manufacturer	OBO
Dimension	200x500
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Piece
Weight	216.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	6,731 kg CO2e / 1 Piece


Technical data sheet

Adjustable connector 200 FT

Item number: 6083210



Dimensions

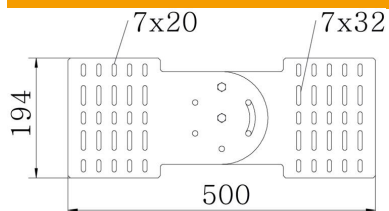

Length	500 mm
Width	16 mm
Height	194 mm
Height	8 in
Plate thickness	2.5 mm

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	200 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	yes
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector