

Technical data sheet

USB charging device

Item number: 6105312



USB charging device with USB Type-A and Type-C sockets for one to two mobile devices (e.g. mobile telephones or tablets). Suitable for installation in Rapid 45 device installation ducts, Rapid 80 device installation ducts, service poles and underfloor systems for indoor application.




PC

Polycarbonate

Master data

Item number	6105312
Type	MTG-2UC QC SWGR1
Description 1	USB charger
Description 2	with 3.0 A charging current
Manufacturer	OBO
Dimension	45x45x42
Colour	Black-grey; RAL 7021
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	6.4 kg
Weight unit	kg/100 pc.

Dimensions

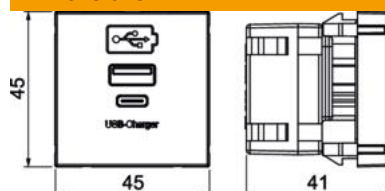

Width	45 mm
Height	45 mm

Technical data sheet

USB charging device

Item number: 6105312



Technical data

Surface version	Matt
Fastening type	Lock
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
ROHS-conformant	yes
Protection rating	IP20
Depth	45 mm
Support ring	no
Transparent	no
Use	USB
Strain relief option	no
Combination	Basic element with central cover plate