

Technical data sheet

Trunking connector and joint cover

Item number: 6113210



Joint cover for the bases of the Rapid 45 device installation trunking to hide cut edges and provide a perfect connection of the trunking segments. The joint covers are attached. Suitable for trunking width 130 mm.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6113210
Type	GK-KS45-2RW
Description 1	Joint cover
Description 2	for Rapid 45-2 130
Manufacturer	OBO
Dimension	133x55x15
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	6
Unit of quantity	Piece
Weight	0.707 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0493 kg CO2e / 1 Piece


Technical data sheet

Trunking connector and joint cover

Item number: 6113210



Dimensions

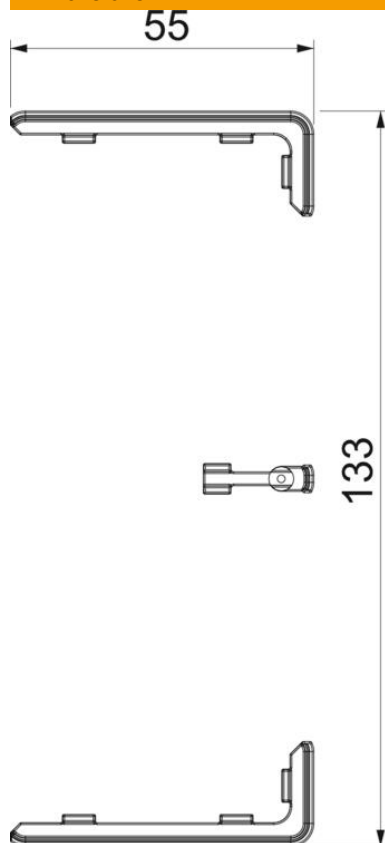

Length	15 mm
Width	55 mm
Height	17 mm

Technical data

Version for	Trunking cut cover
Fastening type	Slide (before mounting)
Shape	Symmetrical
for duct width	130 mm
for trunking height	53 mm
Halogen-free	yes
Cover width	45 mm
ROHS-conformant	yes
Protection rating	IP40
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C