

Technical data sheet

Partition GK-TW53

Item number: 6113290



Partition for mounting in Rapid 45-2 GK and GA device installation trunking for installing cables of different voltage levels.



PVC Polyvinylchloride

Master data

Item number	6113290
Type	GK-TW53
Description 1	Partition
Description 2	for Rapid 45-2
Manufacturer	OBO
Dimension	38x13x2000
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	14.35 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,302 kg CO2e / 1 Meter


Technical data sheet

Partition GK-TW53

Item number: 6113290



Dimensions

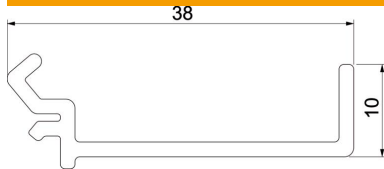

Length	2,000 mm
Width	10 mm
Height	38 mm

Technical data

Version for	Single
Fastening type	Plug-in
Suitable for duct depth	53
Halogen-free	no
ROHS-conformant	yes
Protection rating	IP40
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C